

SPECIAL BOLTS FOR TENSION LINK / TENSION LINK RETAINERS



Printed in Red


The volume discount rate is also applicable to alteration cost.
All price & lead time are to be quoted.

Special Bolts for Tension Link

RoHS



LKB

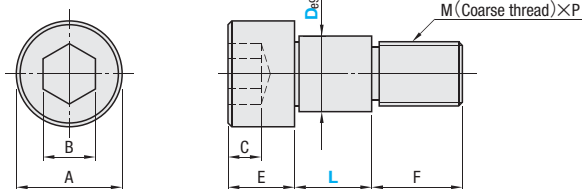

M SCM435
H 33~38HRC
S Black oxide (Fe3O4)


De _g	A	B	C	E	F	M×P	Link A size	Catalog No. Type	D	L	U/Price 1~9
10	-0.025 -0.061	16	6	4	8	12	8×1.25	LKB	10	13	Quotation
13	-0.032 -0.075	18	8	5	10	16	10×1.5		13		
16	-0.040 -0.092	24	10	7	14	18	12×1.75		16		
20	-0.040 -0.092	27	14	9	18	24	16×2.0		20		

Tension Link Retainers

RoHS



LKR (①+②)
LKR B (① only)

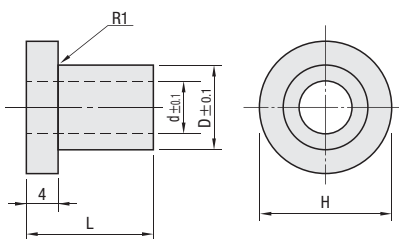

① Retainer
M S45C
H 38~43HRC
S Black oxide (Fe3O4)
② Socket head cap screws

Retailer+Bolt

Link A size	d	D	H	L	② Bolt	Catalog No.		U/Price 1~9
						Type	No.	
19	6.5	10	13	16	CB 6-25	LKR	10	Quotation
							24	
25	9	13	16	16	CB 8-30	(①・②)	13	Quotation
							24	
32	11	16	19	16	CB10-30	(Retainer, bolt)	16	Quotation
							24	
38	13	20	23	16	CB12-35		20	Quotation
							24	

Retainer Only


Catalog No. Type	No.	U/Price 1~9
	10-24	
	13	Quotation
	13-24	
	16	Quotation
	16-24	
	20	Quotation
	20-24	

Tension Link Retainers

RoHS



LKT (①+②)
LKT B (① only)

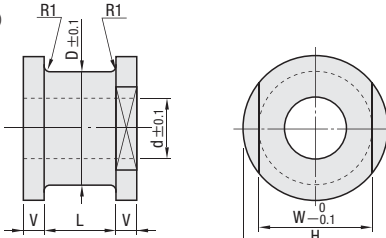

① Retainer
M S45C
H 38~43HRC
S Black oxide (Fe3O4)
② Socket head cap screws

Retailer+Bolt

Link A size	d	D·W	H	L	V	② Bolt	Catalog No.		U/Price 1~9
							Type	No.	
19	6.5	10	16	11	3	CB 6-30	LKT	10	Quotation
								18	
25	9	13	19	11	3	CB 8-35	(①・②)	13	Quotation
								18	
32	11	16	22	11	3	CB10-35	(Retainer, bolt)	16	Quotation
								18	
38	13	20	26	11	3	CB12-40		20	Quotation
								18	

Retainer Only

Catalog No. Type	No.	U/Price 1~9
	10-18	
	13	Quotation
	13-18	
	16	Quotation
	16-18	
	20	Quotation
	20-18	



Order

Catalog No. — L

LKB 13 — 20
LKR 13
LKT10-18



Delivery

Printed in Red

SGP Stock

Printed in Blue

3 Days

For area out of Singapore please refer to P.i.

Quantity discount rate

Quantity Rate	1~9	10~19	20~49	50~100
	—	5%	10%	15%

Stocks Availability Subjected to Prior Sales.