


MOLD OPENING PREVENTION PLATES

—STANDARD TYPE—



Printed in Red

The volume discount rate is also applicable to alteration cost.
All price & lead time are to be quoted.

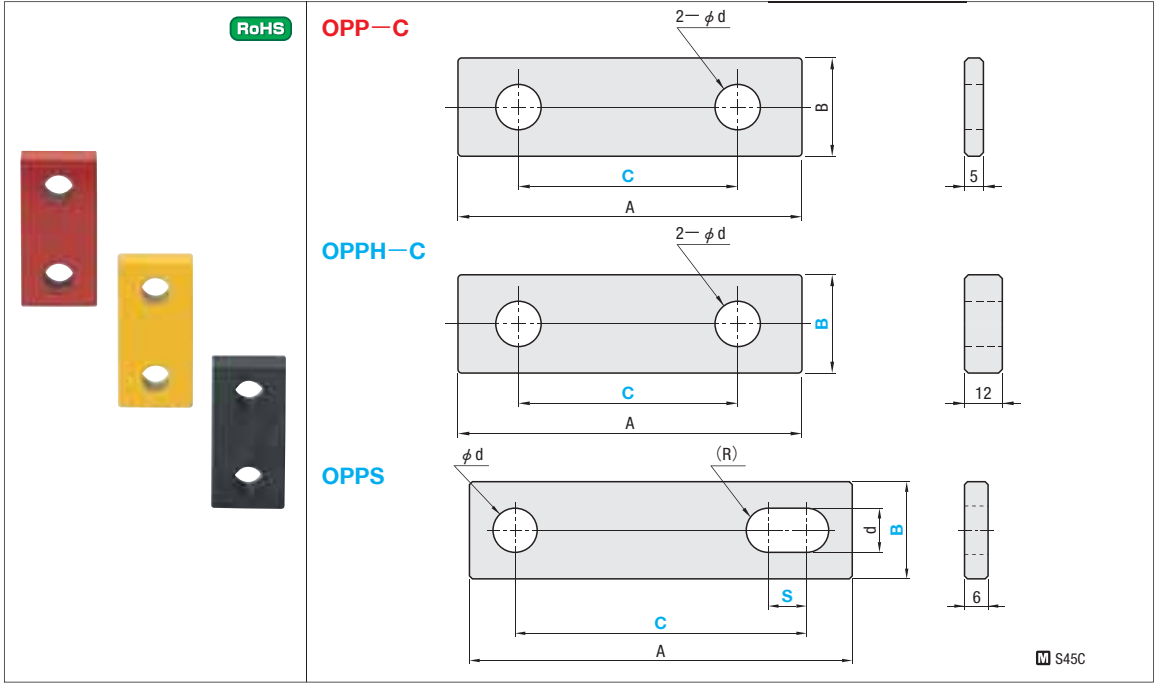

B	A	d	Catalog No.		Color Safety coloring	U/Price 1~9
			Type	C		
16	7	7	OPP-C	15	R (Red) Y (Yellow) N (Normal)	Quotation
				20		
				30		
				40		
				50		
				60		
				70		
				80		
20	9	9	OPP-C	80	R (Red) Y (Yellow) N (Normal)	Quotation
				90		
				100		
				110		
				100		

d	A	Catalog No.		C	S Selection	Color Safety coloring	U/Price 1~9
		Type	B				
7	7	25	OPP-C	30	5 8 10	R (Red) Y (Yellow) N (Normal)	Quotation
				40			
				50			
				60			
				70			
9	9	38	OPPS	80	5 8 10	R (Red) Y (Yellow) N (Normal)	Quotation
				90			
				100			
				110			
				120			
				130			
				140			
				150			
				120			
				130			

d	A	Catalog No.		C	Color Safety coloring	U/Price 1~9
		Type	B			
9	9	25	OPPH-C	20	R (Red) Y (Yellow) N (Normal)	Quotation
				30		
				40		
				50		
				60		
				70		
				80		
14	14	38	OPPH-C	50	R (Red) Y (Yellow) N (Normal)	Quotation
				60		
				70		
				80		
				90		
				100		
				100		



Order

Catalog No. — C — S — Color

OPP-C100 — — — Y
 OPPH-C25 — 50 — — R
 OPSS25 — 30 — 5 — Y



Delivery

• Printed in Red • OPP-C • OPPH-C • Printed in Blue

SGP Stock 3 Days

• OPSS

5 Days Express T Express A P.i

For area out of Singapore please refer to P.i.

Quantity discount rate

Quantity	1~9	10~19	20~49	50~100
Rate	—	5%	10%	15%