


LIFTING EYE BOLTS / LIFTING T-SHAPED BOLTS


 
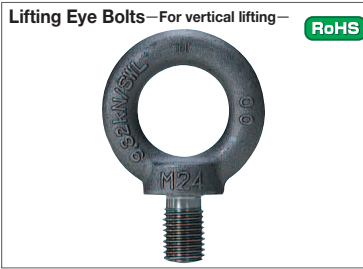


Printed in Red

The volume discount rate is also applicable to alteration cost. All price & lead time are to be quoted.



CHI

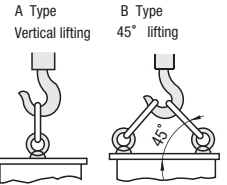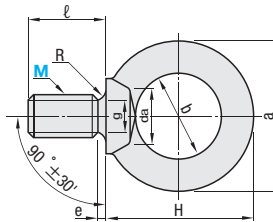


SS400 Bolt precision JIS1168

M×P (Coarse thread)	a	b	C	D	H	ℓ	e	g	R	da	Maximum allowance load N {kgf}		Part Number Type	U/Price M	Side Unit Price					
											A: Vertical 1 Pc.	B: 45° 2 Pcs.			1~19	20~49	50~99	100~200		
M 6×1.0	24.9	14.5	5.2	12.8	28.45	15	3	4.7	1.0	7.9	392 {40}	392 {40}	CHI	6	Quotation					
M 8×1.25	32.6	20	6.3	16	33.3	15	3	6	1.0	9.2	785 {80}	785 {80}				8				
M10×1.5	41	25	8	20	41.5	18	4	7.7	1.2	11.2	1471 {150}	1471 {150}				10				
M12×1.75	50	30	10	25	51	22	5	9.4	1.4	14.2	2157 {220}	2157 {220}				12				
M16×2.0	60	35	12.5	30	60	27	5	13	1.6	18.2	4413 {450}	4413 {450}				16				
M20×2.5	72	40	16	35	71	30	6	16.4	2	22.4	6178 {630}	6178 {630}				20				
M24×3.0	90	50	20	45	90	38	8	19.6	2.5	26.4	9316 {950}	9316 {950}				24				
M30×3.5	110	60	25	60	110	45	8	25	3	33.4	14710 {1500}	14710 {1500}				30				
M36×4.0	133	70	31.5	70	131.5	55	10	30.3	3	39.4	22555 {2300}	22555 {2300}				36				
M42×4.5	151	80	35.5	80	150.5	65	12	35.6	3.5	45.6	33342 {3400}	33342 {3400}				42				
M48×5.0	170	90	40	90	170	70	12	41	4	52.6	44130 {4500}	44130 {4500}	48							


• Load {kgf} = Load N × 0.101972

How to Mount

Fasten the eye bolt lightly by hand until its seat firmly sits on the plate.

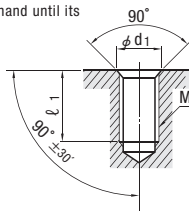


 When using two-bolts of the eye bolts, set them in the same direction.



Caution
Bad example



These applications shown below should never be practiced.

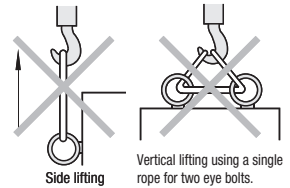

Part Number	d ₁	ℓ ₁
6	9	17
8	11	17
10	13	20
12	16	24
16	20	30
20	24	34
24	28	42
30	36	50
36	42	60
42	48	70
48	56	76



TB

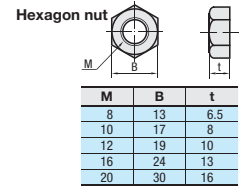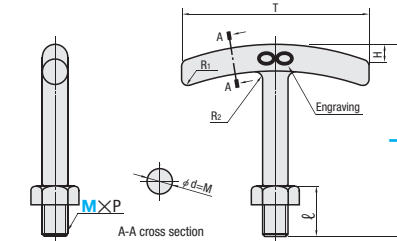

SS400 Bolt precision JIS1168
Hexagon nut

M×P (Coarse thread)	H	R ₁	R ₂	T	R	N/1P {kgf/1P}	Part Number Type	M	L	U/Price 1~19
M10×1.5	8	3	5	80	28	981 {100}	10	110		
M12×1.75	8	3	5	90	34	1471 {150}	12	125		
M16×2.0	10	5	6	100	45	2942 {300}	16	135		
M20×2.5	10	5	8	120	50	3923 {400}	20	160		

• Load {kgf} = Load N × 0.101972



Order

Part Number — L
CHI10
TB12 — 125



Days to Ship


Printed in Red
SGP Stock

Printed in Blue
3 Days



Caution

These applications shown below should never be practiced.

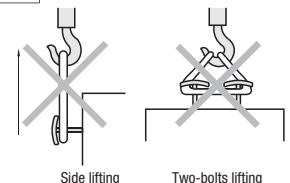

Quantity discount rate

Quantity	1~19	20~49	50~99	100~200
Rate	—	5%	10%	15%

How to Mount
(Lifting T-shaped Bolts)

Fasten the T-shaped bolt lightly by hand, and tighten the nut until it firmly sits on the plate.

※ Tightening the nut this way allows you to freely adjust the T-bar orientation.

Stocks Availability Subjected to Prior Sales.