
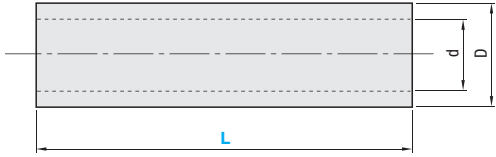




The volume discount rate is also applicable to alteration cost. All price & lead time are to be quoted.

■ Rubber Hose for High-Temperature Water **KGH** (Rubber Hose for High-Temperature Water)

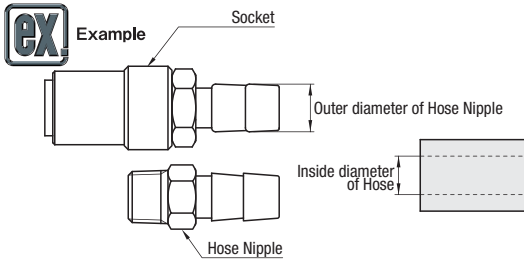



☑ Applicable for liquid-water

M	Internal / Outside rubber	Reinforcing wire
	Heat resistant synthetic rubber (EPDM)	Aramid fiber

D	d	Part Number		L (unit: m)	U/Price 1~9							Maximum allowable pressure MPa (kgf/cm ²)	Allowable temperature range °C	Minimum bending radius mm	Mass kg/m
		Type	No.		L1	L2	L5	L10	L20	L30					
18	9.7	KGH	3	1 2 5 10 20 30	Quotation							1.0(10.2)	-30~120	120	0.23

- ☑ To be quoted on price & lead time above Max. Q'ty.
- ☑ Check the size of the outer diameter of the hose nipple on usage. Although the inside diameter (d) of the hose is 9.7, applicable for hose nipple of outside diameter of between 9.7 and 12mm.



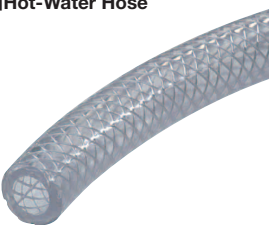
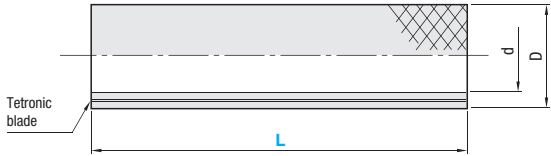
- ☑ Notes**
- When installing the hose nipple, fix it with a hose band (MHBS).
 - This product is for warm water use. NEVER use it with oil. Also, do not use these hoses in an environment where they are likely to come into contact with oil.
 - Inspect the hoses periodically, and if they show signs of cracking, hardening or other changes, replace them.
 - The hoses expand or contract depending upon whether they are pressurized or depressurized, so allow a certain margin of length.

☑ Order **Part Number** — **L**
KGH3 — **10**

☑ Days to Ship **5** Days

☑ For area out of Singapore please refer to P.i.

■ Hot-Water Hose **MHW** (Hot-Water Hose)

☑ Applicable for liquid-water

☑ Soft vinyl chloride

D	d	Part Number		L (unit: m)	U/Price 1~9			Part Number	Specifications			
		Type	No.		L10	L20	L50		Allowable Pressure kPa (kgf/cm ²)	Destructive pressure kPa (kgf/cm ²)	Min. bend radius (room temp.)	Allowable Temperature Range
13.5	8	MHW	1	10 20 50				MHW1	0~1000(0~10)	5500(55)	56	0~60°C
18	12		2					MHW2	0~800(0~8)	4000(40)	84	
22	15		3					MHW3		6000(60)	105	

☑ Order **Part Number** — **L**
MHW2 — **10**

☑ Days to Ship **5** Days


☑ Express T
Express A

☑ For area out of Singapore please refer to P.i.

■ Quantity discount rate

Quantity	1~9	10~19	20~49	50~100
Rate	—	5%	10%	15%

■ Hose Band **MHBT** RoHS



External hose (mm)	Max. tightening torque	Part Number		U/Price
Diameter	N · cm {kgf · cm}	Type	No.	1~9
φ 13~20	350(35)	MHBT	1	Quotation
φ 18~25			2	

☑ Order **Part Number**
MHBT1

☑ Days to Ship **Printed in Red**
SGP Stock

☑ For area out of Singapore please refer to P.i.

■ Quantity discount rate

Quantity	1~9	10~19	20~49	50~100
Rate	—	5%	10%	15%

■ Features MHBT has a safety cap and you are free from concerns to hurt yourself.

Stocks Availability Subjected to Prior Sales.

☑ SUS430
Safety cap: PE
Bolt: SWCH10K